



You are what you breathe

Presenting

Klarwinā



An air purifier range designed to enable the best in your loved ones



High grade
H13 HEPA filter




5-stage air purification



360° airflow



18-stage fan speed

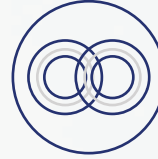

Castor wheels



Wi-Fi control



Alexa enabled



From the Air Experts The Carrier Klarwind range

Klarwind 23S
CADR: 642m³/h
Covers up to 950 sq. ft.




Klarwind 18S
CADR: 468m³/h
Covers up to 700 sq. ft.



5-stage air purification

Featuring a High Grade H13 True HEPA Filter that arrests up to 99.95% PM2.5 particles.

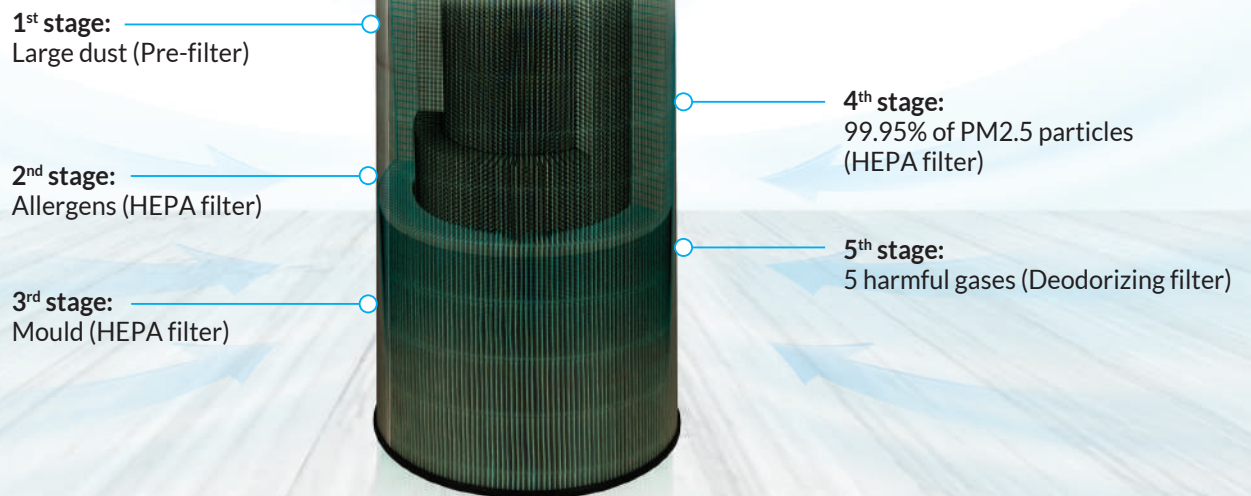

360° airflow

Experience pure air in every corner

Your Klarwind air purifier comes equipped with a patented super power hybrid fan that combines high-performance inhalation with long-distance airflow, to give you pure air everywhere.



Ventilation sensor with deodorizing filter

Klarwind's state-of-the-art sensor and LED GAS indicator helps you keep a check on indoor gas levels, while the deodorizing filter removes gases and odor.

GAS indicator



PureMax technology

Control the speed of purification more precisely, with the world's first 18-stage fan speed control function.



Monitoring air quality made easy

Along with tracking air quality, Klarwind also keeps you updated on specific PM2.5 and harmful gas levels with its smart LED + digital display.




4-step air quality color display system



A good night's rest is a touch of a button away

Switch on the sleep mode to minimise sound and turn off the LED display and lights, so you can sleep better and wake up fresher.

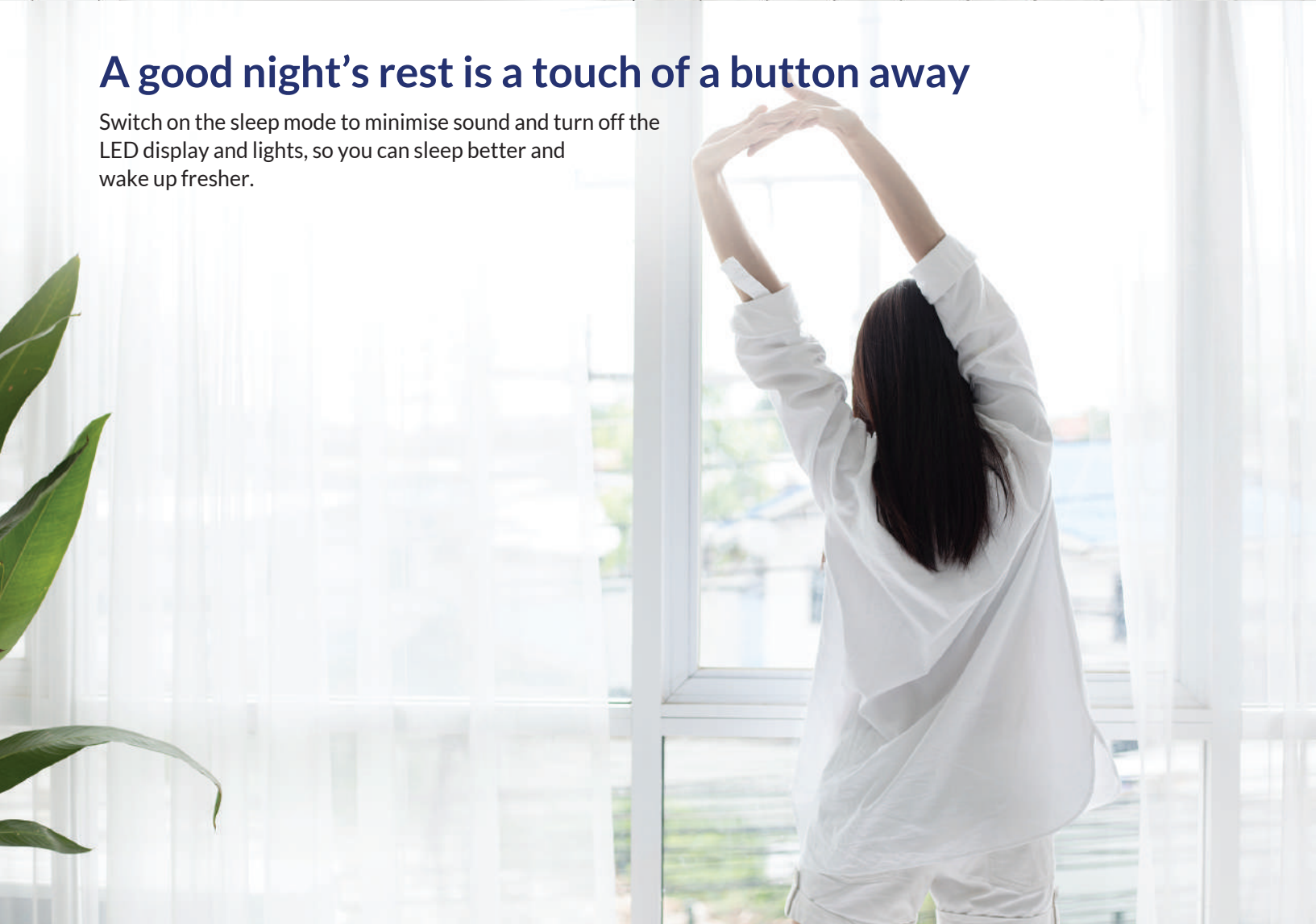


Control settings from the comfort of your bed or, using just your voice!


From changing modes to fan speed, now do it all easily using Alexa or the Klarwind smartapp (available on both iOS and Android).




Switch On/Off

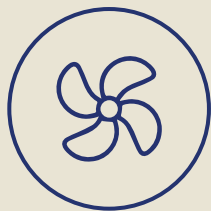


Fan Speed

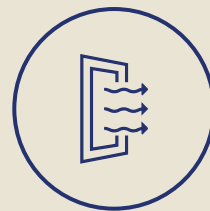

Check Air Quality & Filter Life

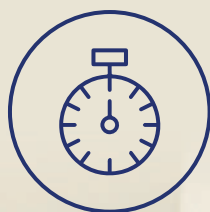

Timer

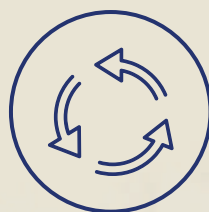

Mode





Carrier

Klarwind

	CADR (m ³ /hr)			Area Covered (sq. ft.)	Product Dimensions WxDxH (cm)	Weight (kg)	Power Consumption (Watt)
	Smoke	Dust	Pollen				
Klarwind 18S	468	485	580	700	34.8x34.8x67.3	10.8	28
Klarwind 23S	642	658	733	950	34.8x34.8x80	12.1	39



CARRIER SERVICE HELPLINE
1800 3000 3545
1800 1021 421

For more details, please contact our sales office:

Corporate & Registered Office: Carrier Airconditioning & Refrigeration Ltd, Kherki Daula Post, Narsingpur, Gurgaon 122004, Tel: 0124-4825500

Sales Offices:- Ahmedabad: 079-44820400 Ghaziabad: 0120-4183260 Bangalore: 080-43442000 Bhubaneswar: 9778030033 Chandigarh: 0172-5007549/50 Chennai: 044-66448888 Cochin: 0484-4029001 Coimbatore: 7397444250 Delhi/NCR: 0124-4873200 Hyderabad: 040-41812233 Indore: 9810204975 Jaipur: 0141-4921737 Kolkata: 033-4059-2000/3000 Lucknow: 0522-4158701 Mumbai: 022-61700700 Pune: 020-48571000/01

CIN: U74999HR1992FLC036104/ Website: www.carrierindia.com/ E-mail: customersupport@carrier.com

