



HEALTHYBUILDINGS



Where Performance Meets Elegance  
**Slim A Air Purifier**


Experience cleaner air for improved living.

Coverage Area: 2400 sq. ft.



# GET CLEANER AIR WITHOUT ANY COMPROMISE.

## Multi-stage Air Filtration System

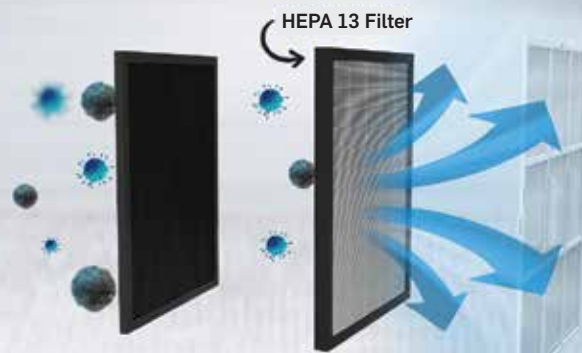

Includes CuS (Copper sulfide) which gives it Anti-Virus\* properties



### H13 HEPA Grade Filter

Effectively removes airborne pathogens and PM 2.5 particles.



### Aesthetics

Elegant design to complement the tasteful surroundings.



### Smart Auto Mode

Automatically adjusts the required air flow based on the built-in air quality sensor.



### Power Efficient

Low power consumption with BLDC motor.

\*Tested with Influenza virus A (H3N2): 99.99% reduction  
Korea Testing & Research Institute



**SLIM A**  
Coverage area: 2400 sq. ft.

## What's more? >>

- Ventilation alert which sends reminder upon identification of high CO2 level
- PM 2.5, VOC and CO2 sensor with display indicator
- 18-level speed control which allows flexible fan speed adjustment
- Remote control for easy operation
- Filter replacement cycle alarm
- Safety lock

## Applications >>



High-end Retail



Office & Hotel Lobbies



Restaurants & Cafes



SERIES NAME		SLIM A
<b>Model name</b>	<b>Unit</b>	<b>CAFN050UC1</b>
Voltage	V/Hz	220-240 V/50
Power Consumption	W	80
Coverage at 3 ACH	m <sup>2</sup>	175
Air Volume	CMH CFM	1,320 775
Motor Type		BLDC
Main Material		ABS+STEEL
Sensor		PM2.5+ VOC Gas Sensor, CO2
Fan Speed		1-18 Steps/Turbo
Noise (Turbo)	dB(A)	56.4
Noise (Low Speed)	dB(A)	34.5
Air Filter Configuration		1) Pre-Filter x 2 (Washable) 2) H13 HEPA Grade Filter x 2 3) Active Carbon Filter x 2
Filter Replacement Remind		Yes
UV		x
Air Quality Indicator		4 Stage (Blue/Green/Yellow/Red)
PM Digital Indicator		PM 2.5, PM 10
CO2 Digital Indicator		Yes
VOC Gas Colour Indicator		Yes
Timer Setting (Hours)		1~24
Dimension (W x D x H)	mm	468*409*1965
Packing Dimension ( W x D x H)	mm	584*491*2035
Weight (Net/Gross)	kg	37.6/42.8
Color		White
Wind Direction Adjustment		Left and Right Flap Automatic
Certificate		CB, EMC

For more information or to find out how to buy - Visit: [www.carrier.com.my](http://www.carrier.com.my) | Email: [cmb.sales@carrier.com](mailto:cmb.sales@carrier.com)

This catalogue provides certain general information and is intended for general guidance only and Carrier is not liable for any damage arising out of the use of the catalogue. The Manufacturer reserves the right to change any product specification without prior notice. All Proprietary Rights Reserved.